


| Rev | Date | Description | By |
|-----|------|-------------|----|
| | | | |

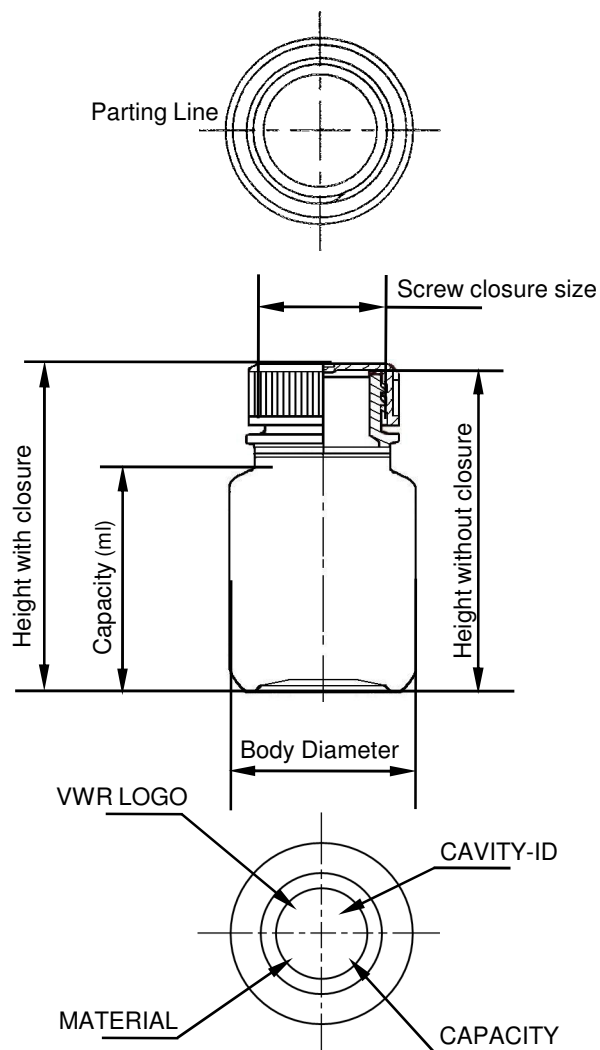

Wide Mouth Bottles Dimension

| Capacity (ml) | VWR Catalog # (Europe) | Bottle Material | Closure Material | Approx. Brim Cap., ml | Color | Screw Closure Size, mm | Height with Closure | Height without closure | Body OD | Neck ID | Product Weight | General Wall Thickness | Autoclaveable |
|------------------|------------------------------|--------------------|---------------------|--------------------------|-------------|------------------------------|---------------------------|------------------------------|------------|------------|-------------------|------------------------------|---------------|
| | | | | | | | MM | MM | | | | MM | |
| 30 | 215-3431 | LDPE | PP | 35 | TRANSLUCENT | 28-415 | 62.5 | 60.0 | 35.0 | 21.5 | 9.5 | 1.25 | NA |
| 60 | 215-3432 | LDPE | PP | 70 | TRANSLUCENT | 28-415 | 85.0 | 82.5 | 38.5 | 21.3 | 13.0 | 1.25 | NA |
| 125 | 215-3433 | LDPE | PP | 140 | TRANSLUCENT | 38-415 | 98.0 | 95.0 | 50.5 | 28.5 | 20.0 | 1.25 | NA |
| 250 | 215-3434 | LDPE | PP | 290 | TRANSLUCENT | 43-415 | 131.0 | 128.0 | 61.5 | 33.0 | 31.0 | 1.25 | NA |
| 500 | 215-3435 | LDPE | PP | 545 | TRANSLUCENT | 53-415 | 169.0 | 164.0 | 72.5 | 43.5 | 59.0 | 1.3 | NA |
| 1000 | 215-3436 | LDPE | PP | 1,030 | TRANSLUCENT | 63-415 | 199.0 | 195.0 | 91.5 | 53.0 | 87.5 | 1.5 | NA |
| 30 | 215-3437 | HDPE | PP | 35 | TRANSLUCENT | 28-415 | 62.5 | 60.0 | 35.0 | 21.5 | 9.8 | 1.25 | NA |
| 60 | 215-3438 | HDPE | PP | 70 | TRANSLUCENT | 28-415 | 85.0 | 82.5 | 38.5 | 21.3 | 13.4 | 1.25 | NA |
| 125 | 215-3439 | HDPE | PP | 140 | TRANSLUCENT | 38-415 | 98.0 | 95.0 | 50.5 | 28.5 | 20.6 | 1.25 | NA |
| 250 | 215-3440 | HDPE | PP | 290 | TRANSLUCENT | 43-415 | 131.0 | 128.0 | 61.5 | 33.0 | 32.0 | 1.25 | NA |
| 500 | 215-3441 | HDPE | PP | 545 | TRANSLUCENT | 53-415 | 169.0 | 164.0 | 72.5 | 43.5 | 60.9 | 1.3 | NA |
| 1000 | 215-3442 | HDPE | PP | 1,030 | TRANSLUCENT | 63-415 | 199.0 | 195.0 | 91.5 | 53.0 | 90.3 | 1.5 | NA |
| 30 | 215-3443 | HDPE | PP | 35 | AMBER | 28-415 | 62.5 | 60.0 | 35.0 | 21.5 | 9.8 | 1.25 | NA |
| 60 | 215-3444 | HDPE | PP | 70 | AMBER | 28-415 | 85.0 | 82.5 | 38.5 | 21.3 | 13.4 | 1.25 | NA |
| 125 | 215-3445 | HDPE | PP | 140 | AMBER | 38-415 | 98.0 | 95.0 | 50.5 | 28.5 | 20.6 | 1.25 | NA |
| 250 | 215-3446 | HDPE | PP | 290 | AMBER | 43-415 | 131.0 | 128.0 | 61.5 | 33.0 | 32.0 | 1.25 | NA |
| 500 | 215-3447 | HDPE | PP | 545 | AMBER | 53-415 | 169.0 | 164.0 | 72.5 | 43.5 | 60.9 | 1.3 | NA |
| 1000 | 215-3448 | HDPE | PP | 1,030 | AMBER | 63-415 | 199.0 | 195.0 | 91.5 | 53.0 | 90.3 | 1.5 | NA |
| 30 | 215-3449 | PP | PP | 35 | TRANSLUCENT | 28-415 | 62.5 | 60.0 | 35.0 | 21.5 | 9.1 | 1.25 | YES |
| 60 | 215-3450 | PP | PP | 70 | TRANSLUCENT | 28-415 | 85.0 | 82.5 | 38.5 | 21.3 | 12.4 | 1.25 | YES |
| 125 | 215-3451 | PP | PP | 140 | TRANSLUCENT | 38-415 | 98.0 | 95.0 | 50.5 | 28.5 | 19.1 | 1.25 | YES |
| 250 | 215-3452 | PP | PP | 290 | TRANSLUCENT | 43-415 | 131.0 | 128.0 | 61.5 | 33.0 | 29.7 | 1.25 | YES |
| 500 | 215-3453 | PP | PP | 545 | TRANSLUCENT | 53-415 | 169.0 | 164.0 | 72.5 | 43.5 | 56.5 | 1.3 | YES |
| 1000 | 215-3454 | PP | PP | 1,030 | TRANSLUCENT | 63-415 | 199.0 | 195.0 | 91.5 | 53.0 | 83.8 | 1.5 | YES |


Title : Wide Mouth Bottle

| | |
|------------|--------------|
| Drawn By | |
| Drawn Date | |
| Scale | Not To Scale |
| Drawing No | |



Material: As per Table

Rev

 —



| Rev | Date | Description | By |
|-----|------|-------------|----|
| | | | |

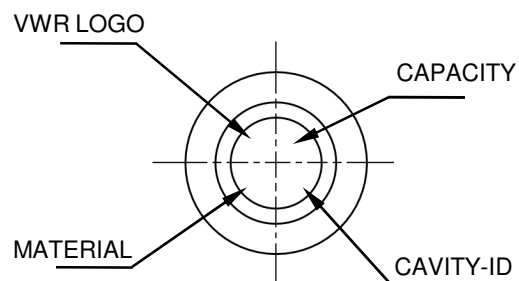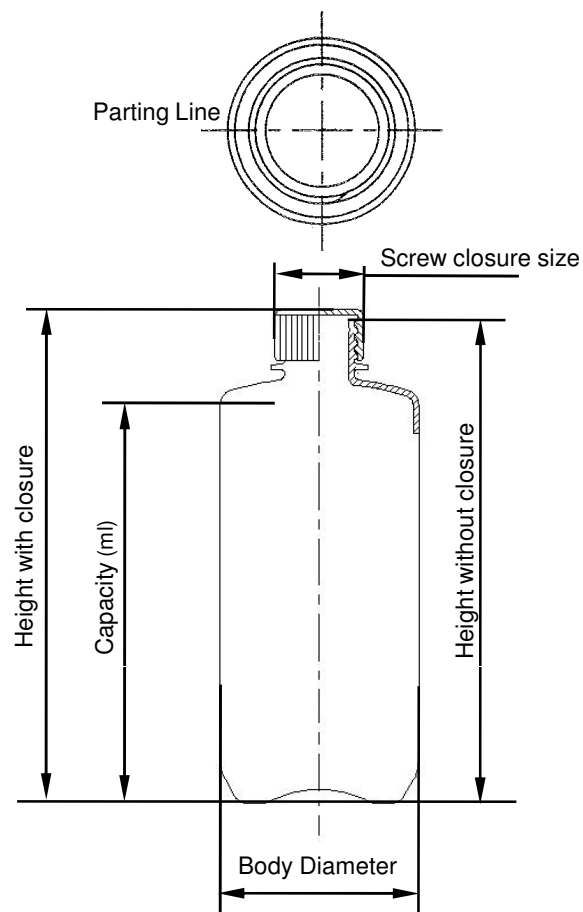

| Capacity ml | Catalog number | Material | Color | Screw Closure Size, mm | Height with Closure | Height without closure | Body Diameter | Autoclave able |
|----------------|-------------------|----------|-------------|------------------------------|---------------------------|------------------------------|------------------|-------------------|
| | | | | | MM | MM | MM | |
| 4 | 215-3400 | HDPE | TRANSLUCENT | 13-415 | 41 | 39 | 16 | NA |
| 8 | 215-3401 | HDPE | TRANSLUCENT | 20-410 | 44 | 42 | 25 | NA |
| 15 | 215-3402 | HDPE | TRANSLUCENT | 20-410 | 58 | 56 | 25 | NA |
| 30 | 215-3403 | HDPE | TRANSLUCENT | 20-410 | 62 | 60 | 36 | NA |
| 60 | 215-3404 | HDPE | TRANSLUCENT | 20-410 | 85 | 83 | 40 | NA |
| 125 | 215-3405 | HDPE | TRANSLUCENT | 24-410 | 100 | 98 | 51 | NA |
| 250 | 215-3406 | HDPE | TRANSLUCENT | 24-410 | 133 | 131 | 61 | NA |
| 500 | 215-3407 | HDPE | TRANSLUCENT | 28-410 | 170 | 167 | 73 | NA |
| 1000 | 215-3408 | HDPE | TRANSLUCENT | 38-430 | 216 | 213 | 92 | NA |
| 4 | 215-3416 | HDPE | AMBER | 13-415 | 41 | 39 | 16 | NA |
| 8 | 215-3417 | HDPE | AMBER | 20-410 | 44 | 42 | 25 | NA |
| 15 | 215-3418 | HDPE | AMBER | 20-410 | 58 | 56 | 25 | NA |
| 30 | 215-3419 | HDPE | AMBER | 20-410 | 62 | 60 | 36 | NA |
| 60 | 215-3420 | HDPE | AMBER | 20-410 | 85 | 83 | 40 | NA |
| 125 | 215-3421 | HDPE | AMBER | 24-410 | 100 | 98 | 51 | NA |
| 250 | 215-3422 | HDPE | AMBER | 24-410 | 133 | 131 | 61 | NA |
| 500 | 215-3423 | HDPE | AMBER | 28-410 | 170 | 167 | 73 | NA |
| 1000 | 215-3424 | HDPE | AMBER | 38-430 | 216 | 213 | 92 | NA |
| 8 | 215-3409 | LDPE | TRANSLUCENT | 20-410 | 44 | 42 | 25 | NA |
| 15 | 215-3410 | LDPE | TRANSLUCENT | 20-410 | 58 | 56 | 25 | NA |
| 30 | 215-3411 | LDPE | TRANSLUCENT | 20-410 | 62 | 60 | 36 | NA |
| 60 | 215-3412 | LDPE | TRANSLUCENT | 20-410 | 85 | 83 | 40 | NA |
| 125 | 215-3413 | LDPE | TRANSLUCENT | 24-410 | 100 | 98 | 51 | NA |
| 500 | 215-3414 | LDPE | TRANSLUCENT | 28-410 | 170 | 167 | 73 | NA |
| 1000 | 215-3415 | LDPE | TRANSLUCENT | 38-430 | 216 | 213 | 92 | NA |
| 8 | 215-3425 | PP | TRANSLUCENT | 20-410 | 44 | 42 | 25 | YES |
| 15 | 215-3426 | PP | TRANSLUCENT | 20-410 | 58 | 56 | 25 | YES |
| 60 | 215-3427 | PP | TRANSLUCENT | 20-410 | 85 | 83 | 40 | YES |
| 125 | 215-3428 | PP | TRANSLUCENT | 24-410 | 100 | 98 | 51 | YES |
| 500 | 215-3429 | PP | TRANSLUCENT | 28-410 | 170 | 167 | 73 | YES |
| 1000 | 215-3430 | PP | TRANSLUCENT | 38-430 | 216 | 213 | 92 | YES |

Title : Narrow Mouth Bottle

| | |
|------------|--------------|
| Drawn By | |
| Drawn Date | |
| Scale | Not To Scale |
| Drawing No | |

Material: As per Table

Rev

—

